

## EPIC® H-A 10 TS


These connectors are attractive because of their compact housing.

The robust metal housing intended for rectangular connectors has a low profile, pivots for a single lever and a side cable entry.

### Info

Non-slip ridges for comfortable disconnecting

Protection rating UL50E tested

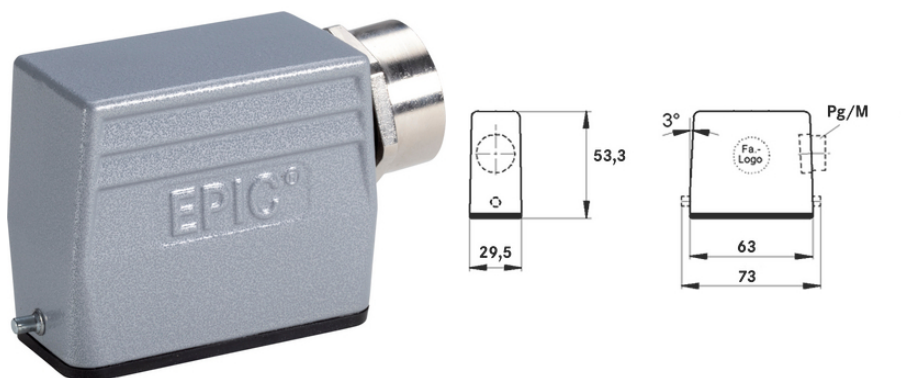

Mechanical and plant engineering



Mechanical resistance



Robust



Waterproof

### Benefits

Small and space-saving for narrow available space

### Application range

Machine and equipment manufacturing

Control engineering

Electronic laboratory

### Product features

Hood, low version

Bolts for single lever

Side cable entry

Versions with neck

Last Update (23.04.2024)

©2024 Lapp Group - Technical changes reserved

Product Management [www.lappkabel.de](http://www.lappkabel.de)

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02\_03.16

## EPIC® H-A 10 TS

### Technical Data

|                        |  |
|------------------------|--|
| Classification ETIM 5: | ETIM 5.0 Class-ID: EC000437<br>ETIM 5.0 Class-Description: Housing for industrial connectors |
| Classification ETIM 6: | ETIM 6.0 Class-ID: EC000437<br>ETIM 6.0 Class-Description: Housing for industrial connectors |
| Material:              | Housing: aluminium alloy, grey<br>Lever: zinc-plated steel<br>Sealing: NBR                   |
| Protection rating:     | IP 65 (latched)<br>NEMA 250, UL50E: 12, 4 (latched)  |
| VDE-tested:            | Certified production control: VDE-REG. no.: B437<br>UL-tested:<br>UL File Number: E75770     |
| Temperature range:     | -40°C to +100°C, short-term up to +125°C   |

### Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.  
Prices are net prices without VAT and surcharges. Sale to business customers only.

**EPIC® H-A 10 TS**

| Article number   | Article description | M  | PG | Neck | Pieces / PU |
|--|---------------------|----|----|------|-------------|
| H-A housing: hood (side cable entry, bolts for single lever) |                     |    |    |      |             |
| 10445000   | H-A 10 TS 16        | -  | 16 | yes  | 5           |
| 10445500   | H-A 10 TS 21        | -  | 21 | yes  | 5           |
| 19445000   | H-A 10 TS M20       | 20 | -  | yes  | 5           |
| 19445500   | H-A 10 TS M25       | 25 | -  | yes  | 5           |