


SILVYN® SEALING WASHER

SILVYN® SEALING WASHER - for metric threads

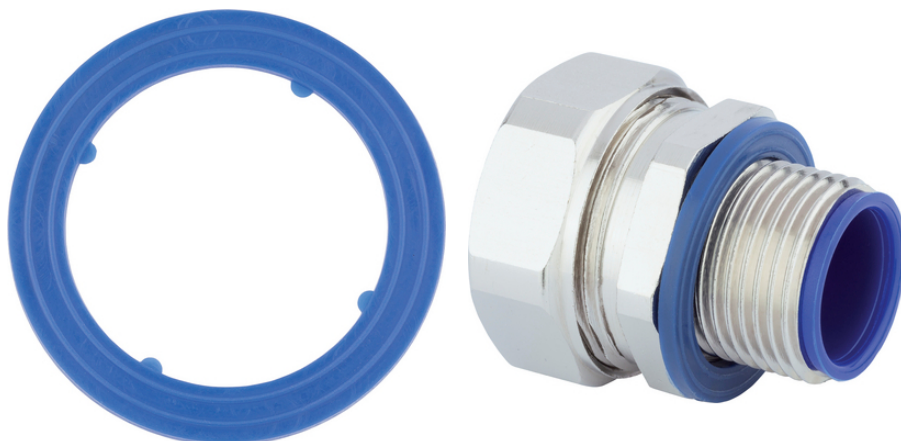

Halogen-free



Maximum vibration protection



Oil-resistant



Reliability

Application range

For sealing the housing reliably to protect against oils, dust, and water at the connection thread of a gland or other similar parts

Product features

Ribs on both faces enhance sealing.

Oil-resistant

Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC001181

ETIM 5.0 Class-Description: Sealing ring

Classification ETIM 6:

ETIM 6.0 Class-ID: EC001181

ETIM 6.0 Class-Description: Sealing ring

Colour delivered:

blue

Material:

Polyester Elastomer

Protection rating:

IP66
IP67
IP68 (5 bar)
IP69

Temperature range:

-50°C to +135°C

Note

Last Update (23.04.2024)

©2024 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16

SILVYN® SEALING WASHER

Photographs and graphics are not to scale and do not represent detailed images of the respective products.
Prices are net prices without VAT and surcharges. Sale to business customers only.

SILVYN® SEALING WASHER

Article number	ID x OD mm	Metric size	Pieces / PU
SILVYN® SEALING WASHER			
61809400	16.0 x 24.0	16 x 1.5	10
61809410	20.0 x 27.0	20 x 1.5	10
61809420	25.0 x 34.0	25 x 1.5	10
61809430	32.0 x 42.0	32 x 1.5	10
61809440	40.0 x 50.0	40 x 1.5	10
61809450	50.0 x 62.0	50 x 1.5	10
61809460	63.0 x 73.0	63 x 1.5	10

Last Update (23.04.2024)

©2024 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16