

61715000	DATA SHEET
Valid from: 26.05.2025	TY-RAP® Cable tie with steel tongue

TY-RAP® cable tie with steel tongue offers a high setting strength that is maintained even under extreme conditions such as large temperature differences, moisture and cold. The fastener is robust and withstands shocks and vibrations. The steel tongue, made of corrosion-resistant and anti-magnetic type 316 steel, is firmly anchored in the binder head.



Material:
Steel nose cap Polyamide 6.6
 Stainless steel

Technical features:
Bundle diameter 1,5 up to 229mm
Belt width 2,4 up to 7,0mm
Tensile strength 80 up to 540N

Further features:
Fire class V2 acc. to UL 94
Halogen free Yes
Silicone-free Yes


Temperature range:
Min. installation temperature -60°C up to +85°C
 -20°C

Colour:
Natural
Black

Approval:  E-file E49405

Standard Reference: 
EN 62275

61715000	DATA SHEET
Valid from: 26.05.2025	TY-RAP® Cable tie with steel tongue

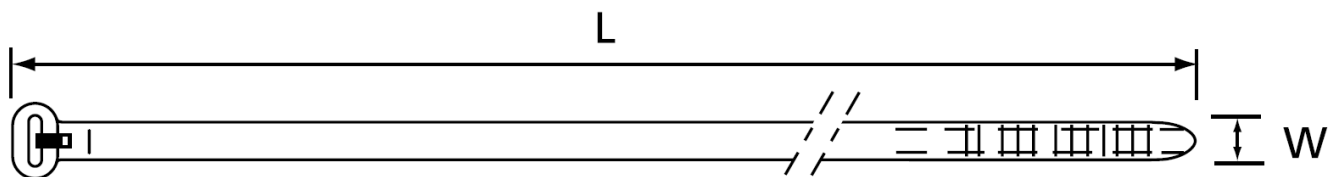

Dimension table:

Article no.	Bundle diameter mm		Dimensions mm			Tensile strength N
	min	max	L	W	Strength	
Cable ties TY-RAP Nature						
61715000	1,5	22	92	2,4	1,0	80
61716250	1,5	51	203	2,4	1,0	80
61716310	1,5	102	356	2,4	1,0	80
61715060	2	35	140	3,6	1,1	178
61715180	2	76	284	3,6	1,1	130
61716370	2	51	208	3,6	1,1	180
61716430	2	102	368	3,6	1,1	134
61715120	3	48	186	4,8	1,1	222
61715300	3	102	361	4,8	1,3	222
61716490	3	78	290	4,8	1,3	222
61715240	6	102	340	7,0	1,6	540
61715360	6	229	771	6,9	1,6	540
61716550	6	51	223	6,9	1,6	534
Cable ties TY-RAP Black						
61723010	1,5	22	92	2,4	1,0	80
61723020	1,5	51	203	2,4	1,0	80
61723040	1,5	102	356	2,4	1,0	80
61723110	2	35	140	3,6	1,1	178
61723120	2	76	284	3,6	1,1	130
61723130	2	51	208	3,6	1,1	180
61723140	2	102	368	3,6	1,1	134
61723030	3	48	186	4,8	1,1	222
61723060	3	102	361	4,8	1,3	222
61723150	3	78	290	4,8	1,3	222
61723050	6	102	340	7,0	1,6	540
61723070	6	229	771	6,9	1,6	540
61723160	6	51	223	6,9	1,6	534

Trade product, not a Lapp product.