


SKINDICHT® GMK

SKINDICHT® GMK, polystyrene counter nuts with PG connection thread, for locking cable glands in boreholes without thread

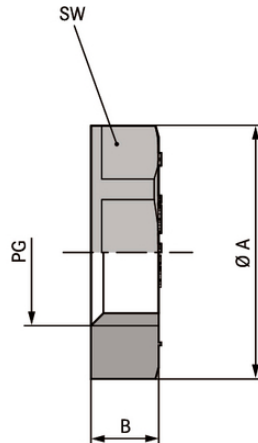

Benefits

Supporting surface for spanner means scratches on the housing are avoided

Application range

For locking SKINDICHT® cable glands in boreholes without thread.

Product Make-up

PG connection thread

Note

SKINTOP® GMP-GL counter nuts are recommended if there are high mechanical stress and high torques for tightening are required

Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC000940

ETIM 5.0 Class-Description: Locknut for cable screw gland

Classification ETIM 6:

ETIM 6.0 Class-ID: EC000940

ETIM 6.0 Class-Description: Locknut for cable screw gland

Colour delivered:

Light grey (RAL 7035)

Material:

Polystyrene

Temperature range:

-20°C to +70°C

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products. Prices are net prices without VAT and surcharges. Sale to business customers only.

SKINDICHT® GMK

Article number	Article designation / size	Height (mm)	SW wrench size mm	Pieces / PU
SKINDICHT® GMK				
52000110	PG 7	5.0	19	100
52000120	PG 9	5.0	22	100
52000130	PG 11	5.0	24	100
52000140	PG 13,5	6.0	27	100
52000150	PG 16	6.0	30	100
52000160	PG 21	7.0	36	50
52000170	PG 29	7.0	46	50
52000180	PG 36	8.0	60	25
52000190	PG 42	8.0	65	25
52000200	PG 48	8.0	70	25

Last Update (11.12.2022)

©2022 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03_16