


SKINDICHT® ZS/ZS-XL

SKINDICHT® ZS/ZS-XL, brass fittings with PG connection thread, as an extension or spare part, -XL offers a long connection thread

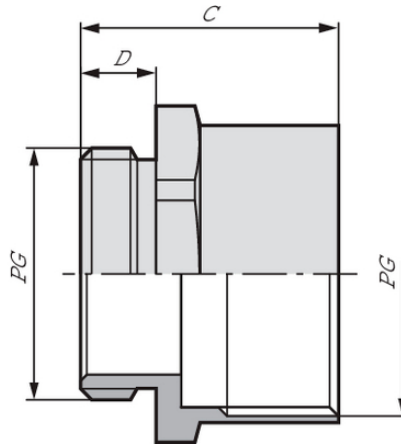

Space requirement

Benefits

Can be used as an extension part or spare part
Assembling with a wrench

Application range

Hexagonal converter from a PG outer thread to a PG inner thread.
Machines
Devices
Housings

Product Make-up

PG connection thread

Note

SKINDICHT® ZS-XL offers a long connection thread

Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC000441
ETIM 5.0 Class-Description: Cable screw gland

Classification ETIM 6:

ETIM 6.0 Class-ID: EC000441
ETIM 6.0 Class-Description: Cable screw gland

Material:

Nickel-plated brass

Temperature range:

-60°C to +200°C

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.
Prices are net prices without VAT and surcharges. Sale to business customers only.

Last Update (26.04.2024)

©2024 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16

SKINDICHT® ZS/ZS-XL

Article number	Article designation / size	SW wrench size mm	Thread length D mm	Pieces / PU
SKINDICHT® ZS				
52100010	PG 7	14	5	100
52100020	PG 9	17	6	100
52100030	PG 11	20	6	100
52100040	PG 13,5	22	6.5	100
52100050	PG 16	24	6.5	50
52100060	PG 21	30	7	50
52100070	PG 29	40	8	25
52100080	PG 36	50	9	10
52100090	PG 42	57	10	10
52100100	PG 48	64	10	10
SKINDICHT® ZS-XL				
52020940	PG 9	17	15	100
52020930	PG 11	20	15	100
52020950	PG 13,5	22	15	100
52020960	PG 16	24	15	50
52020970	PG 21	30	15	50
52020980	PG 29	40	15	25
52020990	PG 36	50	15	10
52021000	PG 42	57	15	10
52021010	PG 48	64	15	10

Last Update (26.04.2024)

©2024 Lapp Group - Technical changes reserved

 Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03_16