


## SKINTOP® HYGIENIC NPT

SKINTOP® HYGIENIC / SKINTOP® HYGIENIC-R, resistant stainless steel cable gland with smooth surfaces for use in product zone

### Info

Ideal for hygienic critical areas - resistant, edge-free, robust and reliable

No gaps, voids or outer lying thread - so no risk of contamination of food machines, facilities or components

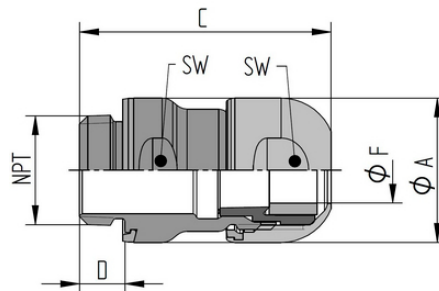

Food & Beverage



Good chemical resistance



Wide clamping range



Mechanical resistance



Robust



Temperature-resistant

### Benefits

Hygienic Design for ideal cleaning results

Smooth surfaces and no edges prevent the accumulation of fluids and formation of micro-organisms

### Application range

Food machinery, equipment and components

For use in **product zone**

Pharmaceutical industry

Last Update (25.12.2023)

©2023 Lapp Group - Technical changes reserved

Product Management [www.lappkabel.de](http://www.lappkabel.de)

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02\_03.16

## SKINTOP® HYGIENIC NPT

### Norm references / Approvals

EHEDG (TYPE EL Class I AUX)

Hygienic design for machinery and components

ECOLAB®

Industry standard in the field of professional cleaning and disinfection in the food and beverage industry

FDA 21 CFR 177.2600

Special sealing element for food and beverage industry in North America

NSF/ANSI 169

Hygienic design for machinery and components

### Product Make-up

Material and shape provide an easy and safe cleaning

By the blue coloring of the sealing material clearly distinguishable from foodstuffs

One complete assembly is easily mounted from the outside

NPT connection thread acc. to ASME B1.20.1 - 2013

### Technical Data

Material:	Body: stainless steel - V4A (1.4404 / 316L) Insert: polyamide Sealing: special elastomer
Protection rating:	IP 68 - 10 bar IP 69 NEMA Type 1, 2, 4x, 6, 12
Temperature range:	-20°C to +100°C

### Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

Prices are net prices without VAT and surcharges. Sale to business customers only.

**SKINTOP® HYGIENIC NPT**

Article number	Article designation / size	Ø F mm	Thread length D mm	SW wrench size mm	Overall length C mm	Pieces / PU
SKINTOP® HYGIENIC NPT						
54114100	NPT 1/4"	4 - 6	7.2	16	39.5	5
54114110	NPT 3/8"	6.5 - 9	7.8	20	42.5	5
54114120	NPT 1/2"	9 - 12	8.4	24	47.0	5
54114130	NPT 3/4"	11.5 - 15.5	8.8	29	50.0	5
SKINTOP® HYGIENIC-R NPT						
54114200	NPT 1/4"	3 - 4.5	7.2	16	39.5	5
54114210	NPT 3/8"	4.5 - 7	7.8	20	42.5	5
54114220	NPT 1/2"	7 - 10	8.4	24	47.0	5
54114230	NPT 3/4"	9 - 12.5	8.4	29	50.0	5

Last Update (25.12.2023)

©2023 Lapp Group - Technical changes reserved

Product Management [www.lappkabel.de](http://www.lappkabel.de)

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02\_03\_16