


SKINTOP® ST-M Small PU

SKINTOP® ST-M, increased oil-resistant plastic cable gland with variable clamping ranges, permanent vibration protection, for offshore platforms

Info

With IP69 approval! Proven to withstand the most demanding cleaning procedures for industrial machinery with high-pressure cleaners and hot water!

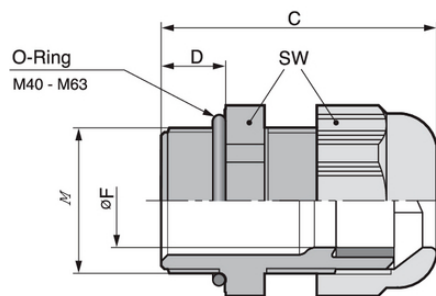

Good chemical resistance



Wide clamping range



Maximum vibration protection



Assembly time



Optimum strain relief



Temperature-resistant



Variety of approval certifications

Benefits

- High oil-resistance for maximum reliability
- Permanent vibration protection
- Wide, variable clamping ranges
- Optimum strain relief
- Various accessories (e.g. multiple sealing inserts)

Last Update (31.01.2023)

©2023 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16

SKINTOP® ST-M Small PU

Application range

Used in areas where a lot of cables and wires need to be inserted into housings with minimum space requirements
Machine and equipment manufacturing
Photovoltaic
Automation technology
Offshore platforms, equipment and shipyards

Norm references / Approvals

UL File Nr. E79903
GGVS: TÜ.EGG.020-95

Product Make-up

Metric connection thread acc. to DIN EN 60423
Basis for technical information DIN IEC 62444

Note

Refer to SKINTOP® metric accessories for suitable accessories
Counter nut to be used: SKINTOP® GMP-GL-M

Technical Data

Classification ETIM 5:	ETIM 5.0 Class-ID: EC000441 ETIM 5.0 Class-Description: Cable screw gland
Classification ETIM 6:	ETIM 6.0 Class-ID: EC000441 ETIM 6.0 Class-Description: Cable screw gland
Caution:	Refer to Appendix T21 for the installation dimensions and torques Size M 40 x 1,5 up to M 63 x 1,5 with O-ring
Colour delivered:	Silver grey (RAL 7001)
Material:	Body: Polyamide Seal: CR
Tests:	GGVS: TÜ.EGG.020-95
Protection rating:	IP 66 IP 68 - 5 bar IP 69 NEMA Type 1, 12
Temperature range:	Fixed: -40 °C to +100 °C Dynamic: -20 °C to +100 °C

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.
Prices are net prices without VAT and surcharges. Sale to business customers only.

SKINTOP® ST-M Small PU

Article number	Article designation / size	Ø F mm	SW wrench size mm	Overall length C mm	Thread length D mm	Pieces / PU
53110146	ST-M 12 x 1,5	3.5 - 7	15	30.0	8	10
53110147	ST-M 16 x 1,5	4 - 10	19	34.0	8	10
53110148	ST-M 20 x 1,5	6 - 13	25	37.0	9	10
53110149	ST-M 25 x 1,5	8 - 17	30	40.0	10	10
53110150	ST-M 32 x 1,5	9 - 21	36	47.0	10	5
53110151	ST-M 40 x 1,5	16 - 28	46	52.0	10	5
53110152	ST-M 50 x 1,5	27 - 34	55	62.0	12	5
53110153	ST-M 63 x 1,5	34 - 45	66	71.0	12	5
53110068	ST-M 12 x 1,5 + GMP-GL-M	3.5 - 7	15	30.0	8	10
53110069	ST-M 16 x 1,5 + GMP-GL-M	4 - 10	19	34.0	8	10
53110070	ST-M 20 x 1,5 + GMP-GL-M	6 - 13	25	37.0	9	10
53110071	ST-M 25 x 1,5 + GMP-GL-M	8 - 17	30	40.0	10	10
53110072	ST-M 32 x 1,5 + GMP-GL-M	9 - 21	36	47.0	10	5
53110073	ST-M 40 x 1,5 + GMP-GL-M	16 - 28	46	52.0	10	5
53110074	ST-M 50 x 1,5 + GMP-GL-M	27 - 34	55	62.0	12	5
53110075	ST-M 63 x 1,5 + GMP-GL-M	34 - 45	66	71.0	12	5

Last Update (31.01.2023)

©2023 Lapp Group - Technical changes reserved

 Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03_16