


SKINTOP® ST Small PU

SKINTOP® ST, increased oil-resistant polyamide cable gland with variable clamping ranges, permanent vibration protection and strain relief

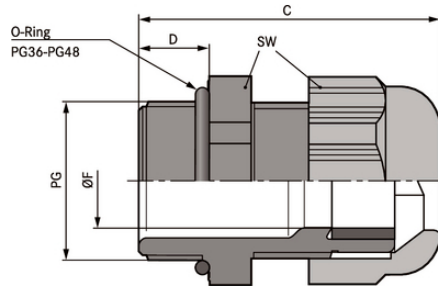

Good chemical resistance



Wide clamping range



Mechanical resistance



Optimum strain relief



Temperature-resistant



Variety of approval certifications

Benefits

- Various accessories (e.g. multiple sealing inserts)
- High oil-resistance for maximum reliability
- Permanent vibration protection
- Optimum strain relief
- Wide, variable clamping ranges

Application range

- Used in areas where a lot of cables and wires need to be inserted into housings with minimum space requirements
- Machine and equipment manufacturing
- Photovoltaic
- Automation technology

Last Update (15.05.2025)

©2025 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16

SKINTOP® ST Small PU

Norm references / Approvals

UL File Nr. E79903

Product Make-up

PG connection thread

Note

Refer to SKINTOP® PG accessories for suitable accessories
Counter nut to be used: SKINTOP® GMP-GL

Technical Data

Classification ETIM 5:	ETIM 5.0 Class-ID: EC000441 ETIM 5.0 Class-Description: Cable screw gland
Classification ETIM 6:	ETIM 6.0 Class-ID: EC000441 ETIM 6.0 Class-Description: Cable screw gland
Caution:	Refer to Appendix T21 for the installation dimensions and torques
Colour delivered:	Silver grey (RAL 7001)
Material:	Body: Polyamide Seal: CR
Tests:	GGVS: TÜ.EGG.020-95
Protection rating:	IP 68 - 5 bar
Temperature range:	Dynamic: -20 °C to +100 °C Fixed: -40 °C to +100 °C

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.
Prices are net prices without VAT and surcharges. Sale to business customers only.

SKINTOP® ST Small PU

Article number	Article designation / size	Ø F mm	SW wrench size mm	Overall length C mm	Thread length D mm	Pieces / PU
53110154	ST 7	2.5 - 6.5	15	32.0	8	10
53110155	ST 9	3.5 - 8	19	36.0	8	10
53110156	ST 11	4 - 10	22	38.0	8	10
53110157	ST 13,5	6 - 12	24	41.0	9	10
53110158	ST 16	9 - 14	27	44.0	10	10
53110159	ST 21	13 - 18	33	49.0	11	5
53110160	ST 29	14 - 25	42	56.0	11	5
53110161	ST 36	24 - 32	53	66.0	13	5
53110162	ST 42	35 - 38	60	68.0	13	5
53110163	ST 48	39 - 44	65	69.0	14	5
SKINTOP® ST small PU + counter nut						
53110080	ST 7 + GMP-GL	2.5 - 6.5	15	32.0	8	10
53110081	ST 9 + GMP-GL	3.5 - 8	19	36.0	8	10
53110082	ST 11 + GMP-GL	4 - 10	22	38.0	8	10
53110083	ST 13,5 + GMP-GL	6 - 12	24	41.0	9	10
53110084	ST 16 + GMP-GL	9 - 14	27	44.0	10	10
53110085	ST 21 + GMP-GL	13 - 18	33	49.0	11	5
53110086	ST 29 + GMP-GL	14 - 25	42	56.0	11	5
53110087	ST 36 + GMP-GL	24 - 32	53	66.0	13	5
53110088	ST 42 + GMP-GL	35 - 38	60	68.0	13	5
53110089	ST 48 + GMP-GL	39 - 44	65	69.0	14	5

Last Update (15.05.2025)

©2025 Lapp Group - Technical changes reserved

 Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03_16