


## EPIC® SENSOR M12 T-distributor

M12 T parallel distributor for CAN/ DeviceNet/ S/A cabling



DeviceNet CANopen

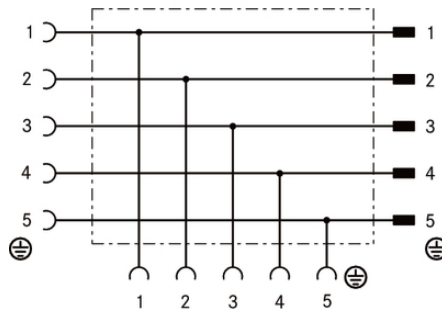

Waterproof



Space requirement



Assembly time



Kompletterande automationskomponenter från Lapp

### Benefits

Cost-effective, efficient wiring of fieldbus and sensor/ actuator installations  
 Space-saving due to compact dimensions  
 Robust design

### Product features

PWIS-free

### Product Make-up

5-pin parallel distributor  
 M12 socket on M12 plug and M12 socket

### Technical Data

Material:

Contact: CuZn  
 Contact surface: Ni/Au  
 Contact carrier: TPU GF  
 Knurl: Zinc die-cast, nickel-plated  
 Gripping body: TPU, flame-retardant, self-extinguishing

Last Update (27.04.2024)

©2024 Lapp Group - Technical changes reserved

Product Management [www.lappkabel.de](http://www.lappkabel.de)

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02\_03.16

## EPIC® SENSOR M12 T-distributor

Protection rating:	Sealing: NBR IP65/IP67
Ambient temperature (operation):	Plug/socket -25°C to +90°C
Coding:	A - Standard (CANopen/DeviceNet/CC-Link)
Rated current (A):	4 A

### Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products. Prices are net prices without VAT and surcharges. Sale to business customers only.

**EPIC® SENSOR M12 T-distributor**

Article number	Article designation
T distributor	
22260765	AB-C5-M12T-2XM12FS DN

Last Update (27.04.2024)

©2024 Lapp Group - Technical changes reserved

Product Management [www.lappkabel.de](http://www.lappkabel.de)

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02\_03\_16