


EPIC® SENSOR M12 T-distributor

M12 T parallel distributor for CAN/ DeviceNet/ S/A cabling



DeviceNet CANopen

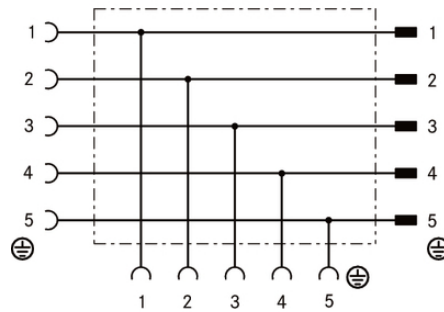

Waterproof



Space requirement



Assembly time



Kompletterande automationskomponenter från Lapp

Benefits

Cost-effective, efficient wiring of fieldbus and sensor/ actuator installations
 Space-saving due to compact dimensions
 Robust design

Product features

PWIS-free

Product Make-up

5-pin parallel distributor
 M12 socket on M12 plug and M12 socket

Technical Data

Material:

Contact: CuZn
 Contact surface: Ni/Au
 Contact carrier: TPU GF
 Knurl: Zinc die-cast, nickel-plated
 Gripping body: TPU, flame-retardant, self-extinguishing

Last Update (13.12.2022)

©2022 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16

EPIC® SENSOR M12 T-distributor

| | |
|----------------------------------|---|
| Protection rating: | Sealing: NBR IP65/IP67 |
| Ambient temperature (operation): | Plug/socket -25°C to +90°C |
| Coding: | A - Standard (CANopen/DeviceNet/CC-Link) |
| Rated current (A): | 4 A |

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products. Prices are net prices without VAT and surcharges. Sale to business customers only.

EPIC® SENSOR M12 T-distributor

| | |
|----------------|-----------------------|
| Article number | Article designation |
| T distributor | |
| 22260765 | AB-C5-M12T-2XM12FS DN |

Last Update (13.12.2022)

©2022 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16