



EPIC® H-A 32 SGRL

Rugged housings for 2 inserts

The robust housing for rectangular connectors consists of 2 double levers and 2 cable entries and can be used, for example, in control systems.

Info

Compact, robust metal housings for double size H-A 32

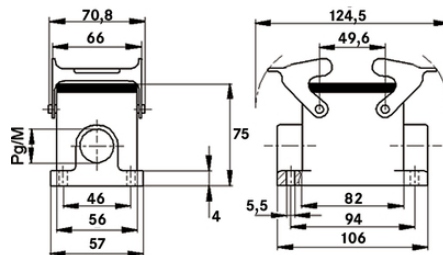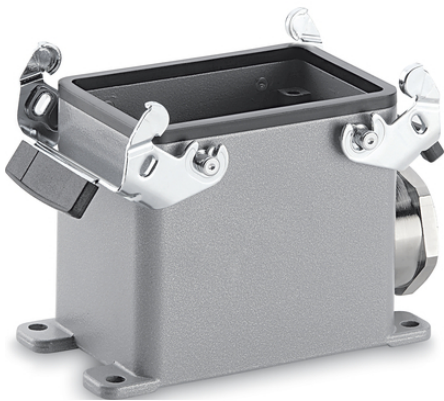

Waterproof



Robust



Mechanical resistance



Mechanical and plant engineering

Benefits

For two inserts of the small H-A, H-D and STA series. Space-saving

Application range

Machine and equipment manufacturing
Control engineering

Product features

Surface-mount base
Dual levers
2 cable entries

Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC000437

Last Update (17.05.2019)

©2019 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16

EPIC® H-A 32 SGRL

Classification ETIM 6:	ETIM 5.0 Class-Description: Housing for industrial connectors ETIM 6.0 Class-ID: EC000437 ETIM 6.0 Class-Description: Housing for industrial connectors
Material:	Housing: aluminium alloy, grey Lever: zinc-plated steel Sealing: NBR
Protection rating:	IP 65 (latched)
VDE-tested:	UL-tested: UL File Number: E75770
Temperature range:	-40°C to +100°C, short-term up to +125°C

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.
Prices are net prices without VAT and surcharges. Sale to business customers only.

EPIC® H-A 32 SGRL

Article number	PL_BEZEICHNUNGARTIKEL	M	PG	Neck
H-A housing: surface-mount base (2 cable entries, double lever)				
10482000	H-A 32 SGRL 21	-	21	yes
19482000	H-A 32 SGRL M25	25	-	yes
19482100	H-A 32 SGRL M32 ZW	32	-	yes
79506800	H-A 32 SGRL M40	40	-	-

Last Update (17.05.2019)

©2019 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16