


EPIC® H-A 48 AG

Rugged housings for 3 inserts

The compact robust metal housing is suitable for accommodating 3 inserts and can be used, for example, in machine and device manufacturing.

Info

Compact, robust metal housings for double size H-A 48

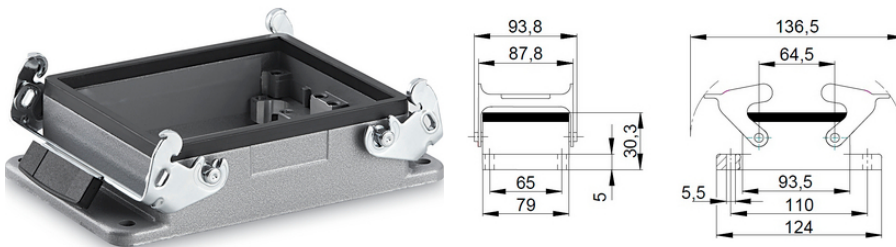

Mechanical and plant engineering



Mechanical resistance



Robust



Waterproof

Benefits

Three different inserts, each suitable for housing type H-A 16, can be integrated in this housing. High flexibility

Application range

Machine and equipment manufacturing

Control engineering

Product features

H-A case: Wall base

Dual levers

Included: flat gasket

Last Update (11.12.2022)

©2022 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16

EPIC® H-A 48 AG

Technical Data

Classification ETIM 5:	ETIM 5.0 Class-ID: EC000437 ETIM 5.0 Class-Description: Housing for industrial connectors
Classification ETIM 6:	ETIM 6.0 Class-ID: EC000437 ETIM 6.0 Class-Description: Housing for industrial connectors
Material:	Housing: powder-coated aluminium alloy, grey Lever: zinc-plated steel Sealing: NBR
Protection rating:	IP 65 (latched)
Temperature range:	-40°C to +100°C, short-term up to +125°C

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.
Prices are net prices without VAT and surcharges. Sale to business customers only.



EPIC® H-A 48 AG

Article number	Article description	Pieces / PU
H-A housing: panel-mount base (double lever)		
10625500	H-A 48 AG	1

Last Update (11.12.2022)

©2022 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16