
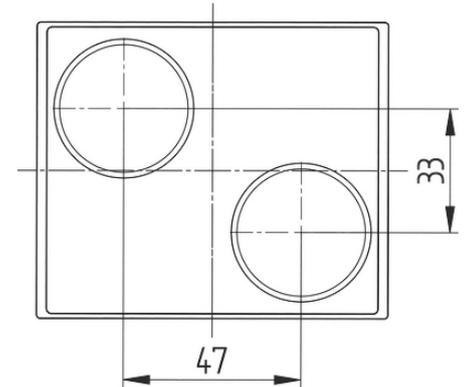


EPIC® H-B 32 TG 2X

Housing design H-B for 2 inserts.

The hood consists of pivots for a single lever, 2 direct cable entries and it is without a neck. It can be used, for example, in investment construction.

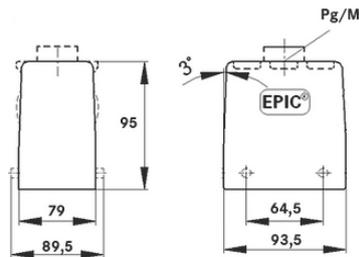

Benefits

Two inserts in one housing. With two levers for high safety

Application range

Plant engineering
Control engineering
Plastics industry

Product features

Hood
Bolts for double lever
2 straight cable entries
Versions without neck

Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC000437

ETIM 5.0 Class-Description: Housing for industrial connectors

Classification ETIM 6:

ETIM 6.0 Class-ID: EC000437

ETIM 6.0 Class-Description: Housing for industrial connectors

Material:

Housing: powder-coated aluminium alloy, grey

Lever: zinc-plated steel

Sealing: NBR

Protection rating:

IP 65 (latched)

Temperature range:

-40 °C to +100 °C, short-term up to +125 °C

Note

Last Update (22.02.2024)

©2024 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16

EPIC® H-B 32 TG 2X

Photographs and graphics are not to scale and do not represent detailed images of the respective products.
Prices are net prices without VAT and surcharges. Sale to business customers only.



EPIC® H-B 32 TG 2X

Article number	Article description	M	Pieces / PU
H-B housing: hood (2 straight cable entries, bolts for double lever)			
44422022	H-B 32 TG 2XM25	2 x 25	5
44422023	H-B 32 TG 2XM32	2 x 32	5

Last Update (22.02.2024)

©2024 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16