


EPIC® H-B 48 AD-LB

Housing design H-B for 2 inserts.

The robust, large panel mount base consists of the housing, a single lever, a seal and a thermoplastic cap and is suitable for investment construction applications.

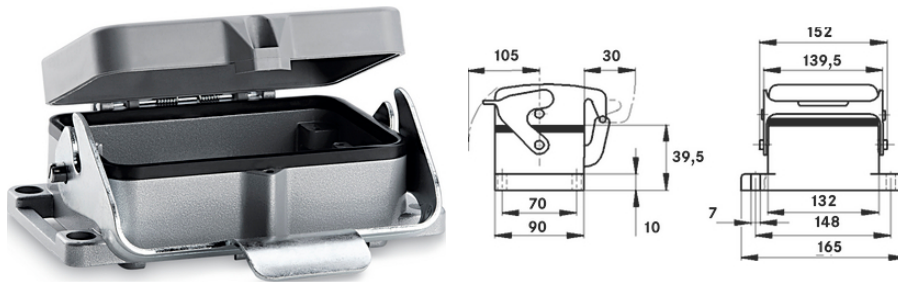

Benefits

The large, robust housing for two inserts in one connector. Power and data in a single connector

Application range

Plant engineering
Plastics industry

Product features

H-A case: Wall base
Single lever
Plastic cover
Included: flat gasket

Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC000437

ETIM 5.0 Class-Description: Housing for industrial connectors

Classification ETIM 6:

ETIM 6.0 Class-ID: EC000437

ETIM 6.0 Class-Description: Housing for industrial connectors

Material:

Housing: powder-coated aluminium alloy, grey

Lever: zinc-plated steel

Sealing: NBR

Protection rating:

IP 65 (latched)

Temperature range:

-40°C to +100°C, short-term up to +125°C

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

Last Update (11.12.2022)

©2022 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16

EPIC® H-B 48 AD-LB

Prices are net prices without VAT and surcharges. Sale to business customers only.

EPIC® H-B 48 AD-LB

Article number	Article description	M	Pieces / PU
H-B housing: panel-mount base (cover, single lever)			
10152000	H-B 48 AD-LB	AG	1

Last Update (11.12.2022)

©2022 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16