


EPIC® H-Q Hood metal

EPIC® H-Q Hood metal housing for H-Q rectangular connector series

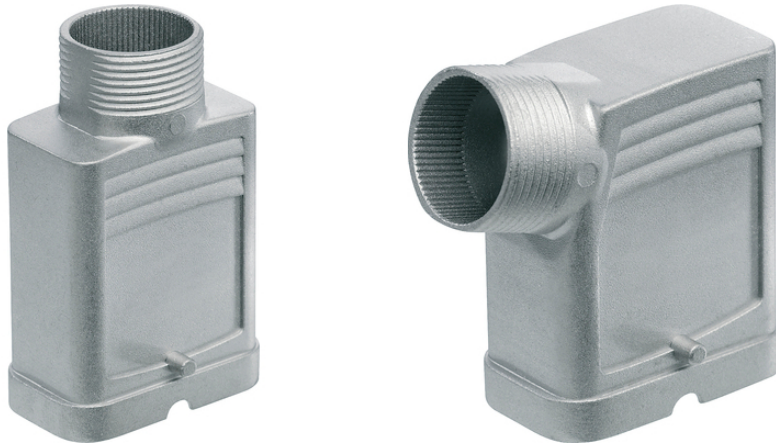

Mechanical and plant engineering



Mechanical resistance



Optimum strain relief



Robust



Interference signals

Benefits

Housing in plastic or metal version. For power supply in the smallest possible space neck for cable gland integrated, use with special H-Q cable glands with metal housing EMC cable gland as an option

Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC000437

ETIM 5.0 Class-Description: Housing for industrial connectors

Classification ETIM 6:

ETIM 6.0 Class-ID: EC000437

ETIM 6.0 Class-Description: Housing for industrial connectors

Material:

Housing: zinc die-casting

Protection rating:

IP 66

Temperature range:

-40°C to +125°C

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products. Prices are net prices without VAT and surcharges. Sale to business customers only.

EPIC® H-Q Hood metal

Article number	Article description	M	Pieces / PU
H-Q housings – hoods (straight cable entry)			
44420539	H-Q TG V21M	V21M	1
H-Q Housing Hood (Cable Entry side)			
44420540	H-Q TS V21M	V21M	1

Last Update (15.02.2020)

©2020 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16