


EPIC® H-Q Hood Plastic

EPIC® H-Q hood plastic housing for H-Q rectangular connector series

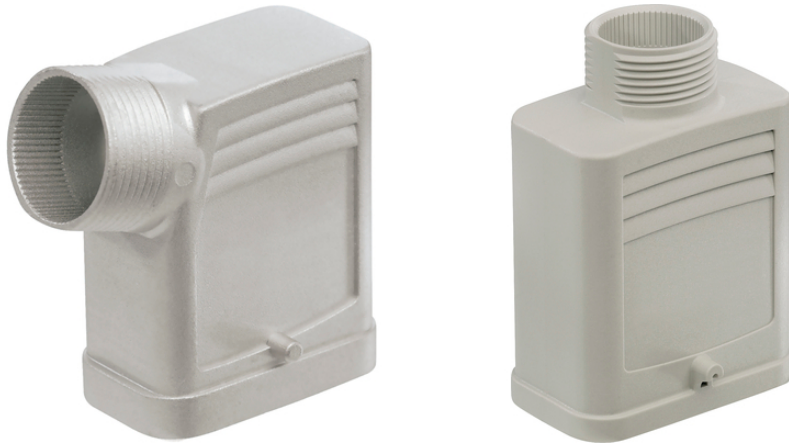

Corrosion-resistant



Low weight



Optimum strain relief

Benefits

Housing in plastic or metal version. For power supply in the smallest possible space neck for cable gland integrated, use with special H-Q cable glands with metal housing EMC cable gland as an option

Application range

Plastic housings for standard applications
Metal housings for increased environmental requirements

Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC000437

ETIM 5.0 Class-Description: Housing for industrial connectors

Classification ETIM 6:

ETIM 6.0 Class-ID: EC000437

ETIM 6.0 Class-Description: Housing for industrial connectors

Material:

Housing: thermoplastic, grey

Lever: metal

Protection rating:

IP 66

Temperature range:

-40°C to +125°C

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products. Prices are net prices without VAT and surcharges. Sale to business customers only.

EPIC® H-Q Hood Plastic

Article number	Article description	M	Pieces / PU
H-Q housings – hoods (straight cable entry)			
44420530	H-Q TG V16P	V16P	1
H-Q Housing Hood (Cable Entry side)			
44420531	H-Q TS V16P	V16P	1

Last Update (22.10.2019)

©2019 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.
PN 0456 / 02_03.16