


## DYMO® Industry Rhino Pro 4200

DYMO® Industry Rhino Pro 4200 is the smallest mobile label printer in the DYMO® series for industrial labelling, ABC keyboard

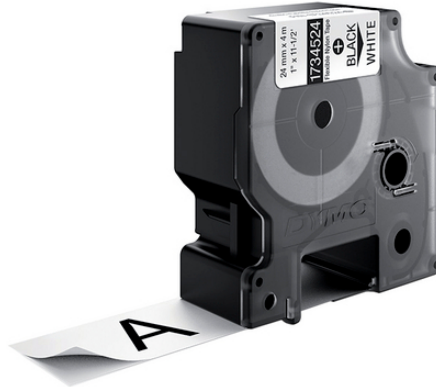

Assembly time



Low weight



Space requirement

### Benefits

Compact and mobile device

Integrated rubber bumpers help prevent damage from accidental drops and falls

Resistant to UV-light, oil, scratches and solvents

Indoor and outdoor applications

### Application range

Marking of cables, wires and components

Coloured self-adhesive vinyl strips

Shrink tubes

### Product features

Thermal transfer printing technology

QWERTY keyboard

### Note

Power cable is not included (art. no. 61800150)

### Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC000608

ETIM 5.0 Class-Description: Labelling tape

Last Update (23.01.2026)

©2026 Lapp Group - Technical changes reserved

Product Management [www.lappkabel.de](http://www.lappkabel.de)

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02\_03.16

## DYMO® Industry Rhino Pro 4200

Classification ETIM 6:	ETIM 6.0 Class-ID: EC000608 ETIM 6.0 Class-Description: Labelling tape
Material:	Vinyl tapes: Vinyl Shrink tube tapes: Polyolefin (flame retardant UL224), shrink ratio 3:1
Temperature range:	Vinyl tapes: -18°C up to +90°C Shrink tube tapes: -18° up to 135°C

### Note

DYMO® is a registered trademark of Sanford GmbH, a Newell Rubbermaid Company  
Photographs and graphics are not to scale and do not represent detailed images of the respective products.  
Prices are net prices without VAT and surcharges. Sale to business customers only.

**DYMO® Industry Rhino Pro 4200**

Article number	Article designation	Width (mm)	Length (m)	For cable Ø (mm)	Colour of tape
61800285	RP/ID1 9mm POLYESTER SW/ TRANSP	9	5.5	-	black-transparent
61800337	DYMO RHINO PRO 4200	-	-	-	-
Vinyl tapes					
61800274	RP/ID1 9mm VINYL SW/WS black	9	5.5	-	white
61800275	RP/ID1 12mm VINYL SW/YELLOW	12	5.5	-	yellow
61800276	RP/ID1 12mm VINYL SW/ORANGE	12	5.5	-	orange
61800277	RP/ID1 12mm VINYL WH/RED	12	5.5	-	red
61800278	RP/ID1 12mm VINYL WH/GREEN	12	5.5	-	green
61800279	RP/ID1 12mm VINYL SW/WHITE	12	5.5	-	white
61800280	RP/ID1 19mm VINYL SW/YELLOW	19	5.5	-	yellow
61800281	RP/ID1 19mm VINYL SW/ORANGE	19	5.5	-	orange
61800282	RP/ID1 19mm VINYL WH/RED	19	5.5	-	red
61800283	RP/ID1 19mm VINYL WH/GREEN	19	5.5	-	green
61800284	RP/ID1 19mm VINYL SW/WHITE	19	5.5	-	white
Shrink tube tapes					
61800290	RP/ID1 Shrink 1-6-1400	6	1.5	1.18 - 2.33	white
61800291	RP/ID1 Shrink 1-9-1400	9	1.5	1.73 - 3.73	white
61800295	RP/ID1 Shrink 1-9-1400YL	9	1.5	1.73 - 3.73	yellow
61800292	RP/ID1 Shrink 1-12-1400	12	1.5	2.97 - 5.13	white
61800296	RP/ID1 Shrink 1-12-1400YL	12	1.5	2.97 - 5.13	yellow
61800293	RP/ID1 Shrink 1-19-1400	19	1.5	4.64 - 8.7	white
61800297	RP/ID1 Shrink 1-19-1400YL	19	1.5	4.64 - 8.7	yellow
61800344	RP/ID1 insertion plate 1-12-1600	12	5.5	-	black-white

Last Update (23.01.2026)

©2026 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02\_03\_16