


FLEXIMARK® Collar for cable tie

FLEXIMARK® Collar for assembly with cable tie for cable and single core marking, flame retardant and halogen-free

Info

By mounting with cable ties independent of the cable diameter

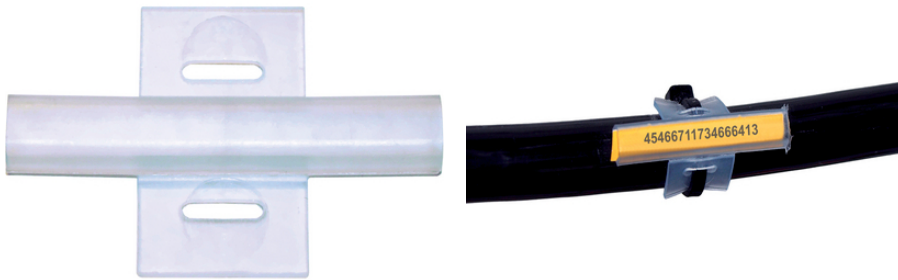

Flame-retardant



Halogen-free

Benefits

Enhanced scratch-protection

Resistant and flexible protection

Resistant to chemicals, UV-light, moisture and oils (diesel oil, basic cleaning agent, sea water, ethanol,...)

Product features

Extremely flame-retardant according to
UL 94 V0

Note

Suitable marking collar for LMB labels

Included

Marking collars without labels

Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC002248

ETIM 5.0 Class-Description: Mounting for labelling material

Classification ETIM 6:

ETIM 6.0 Class-ID: EC002248

ETIM 6.0 Class-Description: Mounting for labelling material

Colour delivered:

Transparent

Material:

Halogen-free polyurethane

Temperature range:

-40°C to +80°C

Last Update (16.02.2025)

©2025 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16

FLEXIMARK® Collar for cable tie

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

Prices are net prices without VAT and surcharges. Sale to business customers only.

FLEXIMARK® products are sold in packaging units. As example if you like to order 640 labels of LCK 32 you just need to order 1 PU instead of 640 single labels.

FLEXIMARK® Collar for cable tie

Article number	Article designation	Length (mm)	Markers / PU	PU
FLEXIMARK® collar for cable ties				
83252676	FLEXIMARK® collar for cable ties	30	200	1

Last Update (16.02.2025)

©2025 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16