


FLEXIMARK® Flexiprint LF

FLEXIMARK® Flexiprint LF are markers for single core marking and marking of glass fibre cables, easy and quick to install.

Info

LF1 included in FLEXIMARK® sample bag (article no. M3251010)

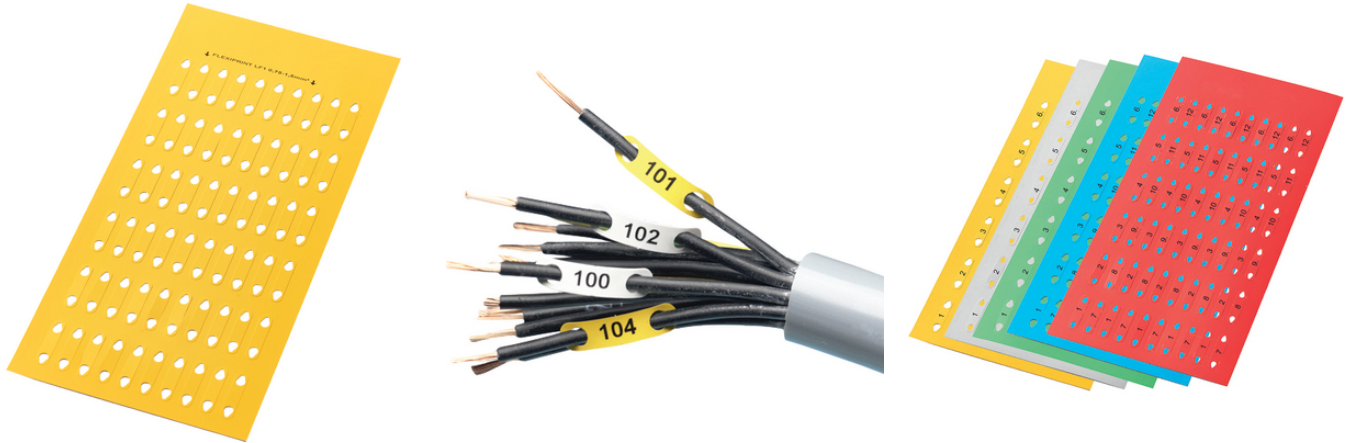

Good chemical resistance



Halogen-free



Assembly time



UV-resistant

Benefits

Resistant to chemicals, UV-light, moisture and oils (diesel oil, basic cleaning agent, sea water, ethanol,...)

Easy to install

Application range

For single core marking

Marking of optical fibre cables

Marking before assembly

For cable cross-sections over 16.00 mm², cable ties can be used for installing single markers

Note

Can be printed with the FLEXIMARK® Software and a commercial laser printer

Insert sheet in manual paper feed compartment

Optimum printing results from laser printers are achieved with straight sheet feed-in

Normal version: Up to 7 characters

L version (e.g. LF1L): Up to 15 characters

Included

One label sheet consists of 20-60 perforated markers, depending on the size

Sheet size: 80-100mm x 210mm

Last Update (23.04.2024)

©2024 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16

FLEXIMARK® Flexiprint LF

Technical Data

Classification ETIM 5:	ETIM 5.0 Class-ID: EC001288 ETIM 5.0 Class-Description: Labelling material
Classification ETIM 6:	ETIM 6.0 Class-ID: EC001288 ETIM 6.0 Class-Description: Labelling material
Colour delivered:	Yellow, white On request: green, blue and red
Material:	Halogen-free polyester Thickness: 0.175 mm
Temperature range:	-40°C to +125°C

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.
Prices are net prices without VAT and surcharges. Sale to business customers only.
FLEXIMARK® products are sold in packaging units. As example if you like to order 640 labels of LCK 32 you just need to order 1 PU instead of 640 single labels.

FLEXIMARK® Flexiprint LF

Article number	Article designation	Colour	A (mm)	A (mm)	C (mm)	D (mm)	E (mm)	For mm ²	Markers / PU
Small packaging (10 sheets)									
83254410	FLEXIMARK® Flexiprint LF0 YE	yellow	22.9	5.2	3.9	13.1	2.4	0.25 - 0.75	600
83254430	FLEXIMARK® Flexiprint LF1 YE	yellow	23	5.2	4.9	11.2	3.5	0.75 - 1.5	600
83254447	FLEXIMARK® Flexiprint LF1L YE	yellow	34	5.2	5	22	3.5	0.75 - 1.5	300
83254470	FLEXIMARK® Flexiprint LF1B YE	yellow	25	5.7	5.9	11.2	4.2	1.5 - 2.5	600
83254487	FLEXIMARK® Flexiprint LF1BL YE	yellow	36	5.7	6	22	4.2	1.5 - 2.5	300
83254510	FLEXIMARK® Flexiprint LF2 YE	yellow	26	7	6.5	11	5.5	2.5 - 6.0	300
83254530	FLEXIMARK® Flexiprint LF3 YE	yellow	41	11	10.5	17	8.4	6.0 - 16.0	200
83254416	FLEXIMARK® Flexiprint LF0 WH	white	22.9	5.2	3.9	13.1	2.4	0.25 - 0.75	600
83254436	FLEXIMARK® Flexiprint LF1 WH	white	23	5.2	4.9	11.2	3.5	0.75 - 1.5	600
83254448	FLEXIMARK® Flexiprint LF1L WH	white	34	5.2	5	22	3.5	0.75 - 1.5	300
83254476	FLEXIMARK® Flexiprint LF1B WH	white	25	5.7	5.9	11.2	4.2	1.5 - 2.5	600
83254488	FLEXIMARK® Flexiprint LF1BL WH	white	36	5.7	6	22	4.2	1.5 - 2.5	300
83254516	FLEXIMARK® Flexiprint LF2 WH	white	26	7	6.5	11	5.5	2.5 - 6.0	300
83254536	FLEXIMARK® Flexiprint LF3 WH	white	41	11	10.5	17	8.4	6.0 - 16.0	200
Large packaging (75 sheets)									
83280005	FLEXIMARK®	yellow	22.9	5.2	3.9	13.1	2.4	0.25 - 0.75	4500

Last Update (23.04.2024)

©2024 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03_16

FLEXIMARK® Flexiprint LF

Article number	Article designation	Colour	A (mm)	A (mm)	C (mm)	D (mm)	E (mm)	For mm ²	Markers / PU
	Flexiprint LF0 YE-75								
83254420	FLEXIMARK® Flexiprint LF1 YE-75	yellow	23	5.2	4.9	11.2	3.5	0.75 - 1.5	4500
83254440	FLEXIMARK® Flexiprint LF1L YE-75	yellow	34	5.2	5	22	3.5	0.75 - 1.5	2250
83254460	FLEXIMARK® Flexiprint LF1B YE-75	yellow	25	5.7	5.9	11.2	4.2	1.5 - 2.5	4500
83254480	FLEXIMARK® Flexiprint LF1BL YE-75	yellow	36	5.7	6	22	4.2	1.5 - 2.5	2250
83254500	FLEXIMARK® Flexiprint LF2 YE-75	yellow	26	7	6.5	11	5.5	2.5 - 6.0	4500
83254520	FLEXIMARK® Flexiprint LF3 YE-75	yellow	41	11	10.5	17	8.4	6.0 - 16.0	1500
83254406	FLEXIMARK® Flexiprint LF0 WH-75	white	22.9	5.2	3.9	13.1	2.4	0.25 - 0.75	4500
83254426	FLEXIMARK® Flexiprint LF1 WH-75	white	23	5.2	4.9	11.2	3.5	0.75 - 1.5	4500
83254446	FLEXIMARK® Flexiprint LF1L WH-75	white	34	5.2	5	22	3.5	0.75 - 1.5	2250
83254466	FLEXIMARK® Flexiprint LF1B WH-75	white	25	5.7	5.9	11.2	4.2	1.5 - 2.5	4500
83254486	FLEXIMARK® Flexiprint LF1BL WH-75	white	36	5.7	6	22	4.2	1.5 - 2.5	2250
83254506	FLEXIMARK® Flexiprint LF2 WH-75	white	26	7	6.5	11	5.5	2.5 - 6.0	4500
83254526	FLEXIMARK® Flexiprint LF3 WH-75	white	41	11	10.5	17	8.4	6.0 - 16.0	1500

Last Update (23.04.2024)

©2024 Lapp Group - Technical changes reserved

 Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03_16

FLEXIMARK® Flexiprint LF

