


SILVYN® LGS-2

SILVYN® LGS-2 is a swivelling nickel-plated brass conduit fitting for installation with torsional movements

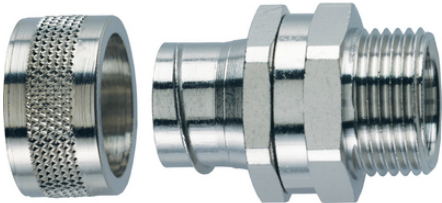

Corrosion-resistant



Mechanical resistance



Oil-resistant



Space requirement



Robust

Benefits

For rotating applications

High tensile strength

Space-saving

Application range

In combination with protective conduit:

SILVYN® LCC-2

SILVYN® LCCH-2

Applications with high mechanical stress

Outdoors

Product Make-up

PG connection thread

Hexagonal collar with torsion element

Cap nut

Last Update (18.05.2025)

©2025 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16

SILVYN® LGS-2**Technical Data**

Classification ETIM 5:	ETIM 5.0 Class-ID: EC001180 ETIM 5.0 Class-Description: Screw connection for protective metallic hose
Classification ETIM 6:	ETIM 6.0 Class-ID: EC001180 ETIM 6.0 Class-Description: Screw connection for protective metallic hose
Norm references / Approvals:	IEC EN 61386-23
Material:	Nickel-plated brass
Protection rating:	IP 54
Temperature range:	-50 °C to +300 °C

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.
Prices are net prices without VAT and surcharges. Sale to business customers only.



SILVYN® LGS-2

Article number	Metric size	SW wrench size mm	Overall length mm	Thread length mm	Suitable for SILVYN® LCC-2 / LCCH-2	Pieces / PU
SILVYN® LGS-2						
55502710	7	13	32	7	10	10
55502720	9	17	38	10	12	10
55502730	11	22	38	10	16	10
55502740	13.5	24	39	12	20	10
55502750	16	24	44	12	20	10
55502760	21	29	50	12	25	10
55502770	29	36	56	12	32	10
55502780	36	48	59	12	40	4
55502790	48	70	61.2	16	63	1

Last Update (18.05.2025)

©2025 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03_16