


FIPLOCK® ONE Conduit holder (stackable)

Conduit fitting system for highest requirements, suitable for FIPLOCK® PA6 / PA12

FIPLOCK® ONE Conduit holder (stackable)

Info

New conduit fitting system with innovative locking system

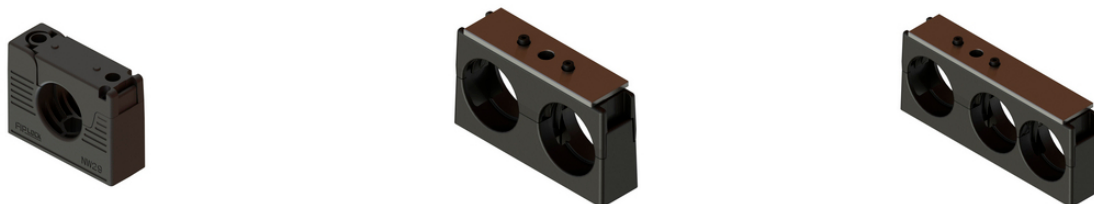

Rail



Good chemical resistance



Flame-retardant



Halogen-free



Cold-resistant



Maximum vibration protection



Mechanical resistance



Assembly time



Low weight

Last Update (22.02.2024)

©2024 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16

FIPLOCK® ONE Conduit holder (stackable)



Optimum strain relief



Robust



Reliability



UV-resistant



Waterproof



Benefits

Very high tensile strength due to all around tooth system
Ensures mounting safety due to integrated coding system
Excellent IP rating
Cost-saving due to quick and easy installation

Application range

Suitable for FIPLOCK® PA6 / PA12
Demand of increased liquid tightness
For indoor and outdoor use

Product features

All around locking mechanism due to 360° tooth system
Locking mechanism with integrated coding system
Extended sealing range across multiple corrugated conduit waves

Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC001176

ETIM 5.0 Class-Description: Screw connection for corrugated plastic hose

Classification ETIM 6:

ETIM 6.0 Class-ID: EC001176

ETIM 6.0 Class-Description: Screw connection for corrugated plastic hose

Certifications:

IEC EN 61386-23

EN 45545-2 HL3

Colour delivered:

Grey (RAL 7005)

Black (RAL 9005), UV-resistant

Material:

PA 6

Halogen-free

Fire behaviour according to UL 94V-0

Protection rating:

IP66/IP67/IP68/IP69

Temperature range:

-45°C to +120°C

Last Update (22.02.2024)

©2024 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16

FIPLOCK® ONE Conduit holder (stackable)

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.
Prices are net prices without VAT and surcharges. Sale to business customers only.

FIPLOCK® ONE Conduit holder (stackable)

Article number	Nominal size	Hole Ø (mm)	Design	Suitable for FIPLOCK® PA6 / PA12	Colour	Pieces / PU
Conduit mounting clamp						
61805116	17	8.5	Single	17	black	10
61805117	23	8.5	Single	23	black	6
61805118	29	8.5	Single	29	black	6
61805119	36	8.5	Single	36	black	4
61805120	48	8.5	Single	48	black	4
61805121	56	8.5	Single	56	black	4
Conduit mounting clamp with ball joint						
61805122	12	8.5	Single	12	black	10
61805123	17	8.5	Single	17	black	6
61805124	23	8.5	Single	23	black	6
61805125	29	8.5	Single	29	black	4
61805126	36	8.5	Single	36	black	4
61805127	48	8.5	Single	48	black	4
Multiple conduit mounting rail						
61805128	2x 36	8.5	Double	36	black	4
61805129	2x 48	8.5	Double	48	black	4
61805130	3x 36	8.5	Triple	36	black	4
61805131	3x 48	8.5	Triple	48	black	4
61805132	4x 36	8.5	Quadruple	36	black	4
61805133	4x 48	8.5	Quadruple	48	black	4

Last Update (22.02.2024)

©2024 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03_16

FIPLOCK® ONE Conduit holder (stackable)