 

 


## Tie screw socket

TC tie screw socket for fastening cable ties

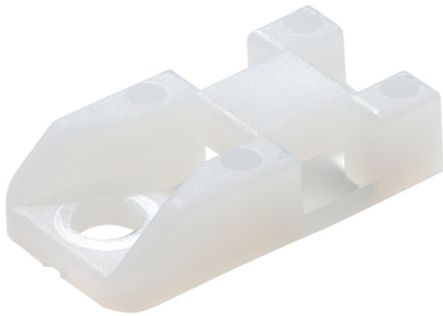

mm	A	B	C	D	F
TC 826	5,7	13,0	24,0	2,0	12,3
TC 828	3,8	10,0	23,0	1,0	13,5



Halogen-free

### Benefits

Low overall height  
Possibility for cross mounting

### Application range

Fastening elements for cable ties  
For fastening with screws or rivets  
Typical areas of application: Control cabinet manufacture, motor vehicles, office machines

### Norm references / Approvals

File number: E49405  
UL 94 V-2

### Included

Delivered without screws

### Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC000449  
ETIM 5.0 Class-Description: Mounting base and -element for cable ties

Classification ETIM 6:

ETIM 6.0 Class-ID: EC000449  
ETIM 6.0 Class-Description: Mounting base and -element for cable ties

Colour delivered:

Natural colour

Material:

Polyamide 6.6  
Halogen-free and silicone-free

Temperature range:

-40°C to +85°C

Last Update (05.07.2020)

©2020 Lapp Group - Technical changes reserved

Product Management [www.lappkabel.de](http://www.lappkabel.de)

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02\_03.16

## Tie screw socket

### Note

This is a product of the company ABB/Thomas & Betts.

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

Prices are net prices without VAT and surcharges. Sale to business customers only.

**Tie screw socket**

Article number	Article description	Fastening type	Material	Diameter (mm)	Tie width (mm)	Weight (g/100 pieces)	Pieces / PU
61724810	TC 826	screwing	PA 6.6	4.2	4.8	197	1000
61724820	TC 828	screwing	PA 6.6	4.2	4.8	40	1000

Last Update (05.07.2020)

©2020 Lapp Group - Technical changes reserved

Product Management [www.lappkabel.de](http://www.lappkabel.de)

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02\_03.16